

Application

Model KFD-350 is a static rated fire damper used in kitchen ventilation system. This model carries a 3 hour UL 555 fire damper label and is static rated for use in HVAC systems that are automatically shut down in the event of a fire.

Ratings

UL 555 Fire Resistance Rating

Fire Rating: 3 hours

Construction

	Standard	Optional
Frame Material	Galvanized steel*	-
Frame Depth	3 1/16 in. (94 mm)	-
Blade Material	Galvanized steel*	-
Closure Spring	Stainless steel	-
Closure Device	Fusible link	-
Closure Temperature	165°F (74°C)	212°F (100°C)
Mounting	Horizontal	-


* in gauges required by UL listing R13317

Options

- Clean wrap

Size Limitations

W x H	Minimum Size	Maximum Single Section Size	Maximum Multi-Section Size
Inches	4 x 4	36 x 16	40 x 40
mm	102 x 102	(914 x 406)	1016 x 1016

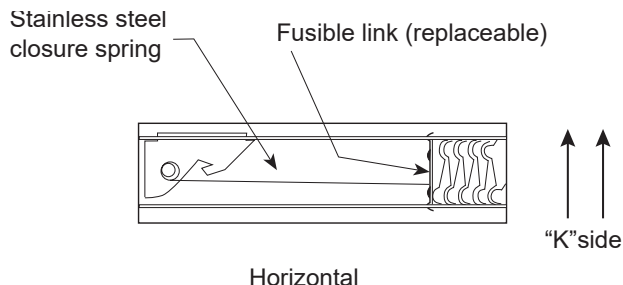

* These dimensions are furnished approximately 1/4 in. (6mm) undersize.



See complete marking on product.
UL 555 Classification R13317

Model KFD-350 meets the requirements for fire damper established by:

National Fire Protection Association
(NFPA Standards 80, 90A & 101)

Underwriters Laboratories Standard 555
(Listing #R13317)

IBC International Building Codes

California State Fire Marshall
(Listing #3225-981:102)

Document Links



[INSTALLATION](#)



[WARRANTY](#)