



April 2025

Business Unit Product Support Directory

PAGE	BUSINESS UNIT
2	<u>Axial, Inline and HVLS Fans</u> - High Volume Low Speed/Circulator - Inline/Gravity - Axial/Propeller
2	<u>Ceiling Exhaust</u> – Residential Energy Recovery, Ceiling Exhaust, Bath and Cabinet Fans
3	<u>CF</u> - Centrifugal Fans
3	<u>FETI</u> – Fume Exhaust and Tubular Inline
4	<u>Dampers</u> - Commercial and Industrial
5	<u>DOAS</u> - Dedicated Outdoor Air Systems and Service
5	<u>ATU</u> – Air Terminal Units
5	<u>RTU</u> – Rooftop Units
6	<u>GRD</u> – Grilles, Registers and Diffusers
7	<u>Louvers</u> – Stationary-Operable-WindDrivenRain-Hurricane - Specialty - Louvered Penthouses
7	<u>Parts</u> - Greenheck Replacement Parts
8	<u>PRV</u> - Power Roof Ventilators / Roof Curbs
8	<u>TAP</u> -Tempered Air Products
9	<u>KVS</u> - Greenheck/Accurex Model Cross Reference

REGIONAL SALES – 1-800-333-8867	
North.sales@greenheck.com – North Central, Great Lakes & Canada, & Midwest	
West.sales@greenheck.com – California, South Central & Mountain	
East.sales@greenheck.com – MidAtlantic, Southeast & Northeast	
CAPS/eCAPS	BIM/Revit
CAPS@greenheck.com	BIM@greenheck.com
1-855-886-8324	1-800-211-4858
1-715-355-6523	1-715-841-8450

CF	Centrifugal Fans		cvifans@greenheck.com
	Blowers/Utility Sets BCSW-FRP, FPB, IP,USF		1-888-284-3306
	Fan Array HPA, MOA		
	Fume Exhaust FumeJet (FJC/FJI)		
Plenum APD, APH, APM, PLG			

FETI	Fume Exhaust and Tubular Inline		Tubular.service@greenheck.com
	Tubular Inlines AX, QEI, QEID, TAUB, TBI, VAB, VAD, GreenJet GJX, GJI		1-877-835-8677
Laboratory Exhaust Vektor-H, Vektor-MH, Vektor-MD, Vektor-MS, Vektor-CH, Vektor-CD, Vektor-CS, Vektor-ERS	vektor.support@greenheck.com 1-877-835-8677		

Dampers

Commercial Dampers

dampers@greenheck.com

Life Safety Dampers:

DFD/FD, FSD, SMD

Control Dampers:

ICD, FBV, VCD, VCDR, VCDRM

Air Measuring:

AMD, AMS

Backdraft:

BD, EM, EMV, GM, WB, WD, WDR

Balancing:

ABD, MBD, MBDR, RBD, RBDR

Relief:

BR, SEBR

Doors:

CAD, HAD, RAD, PRAD, VRAD

Duct Heaters:

IDHB, IDHE, IDHE-O

A collection of various commercial damper components, including rectangular and circular units, some with actuators and control boxes, and duct heaters.

1-800-717-6540

Heavy Duty/Industrial Dampers

HDdampers@greenheck.com

Backdraft:

HB, HBR

Bubble Tight:

HBTR, HBT

Control:

HCD, HCDR

Relief:

HPR

Blast/Tornado:

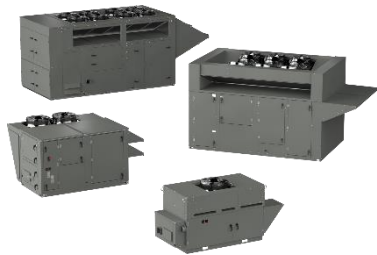
HBS, HTOD

Marine:

HSV, HSVR, HTG, HTGR

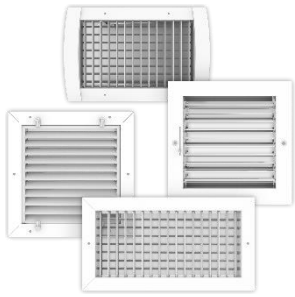
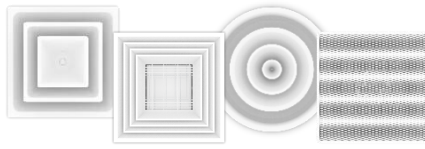
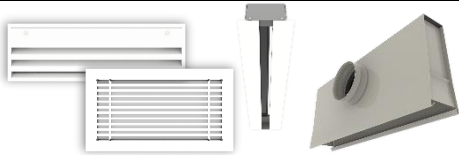
 
 
A collection of various heavy-duty industrial damper components, including rectangular and circular units, some with actuators and control boxes, and duct heaters.

 
1-800-717-6540

DOAS	DOAS Service		DOAS@greenheck.com
	RV/RVE, ERCH, ERT, Remote Condenser (RC)		1-866-478-2574 and Press 1
DOAS	DOAS Pre-Sale		DOAS@greenheck.com
	RV/RVE/RVC/ERCH/ERT/Remote Condensor (RC)		1-866-478-2574 and Press 2

ATU	Air Terminal Units		ATU@greenheck.com
	Single Duct Air Terminals: XG-TH-500, XG-TL-500, XG-BP-600		(727) 431-6000
	Fan Powered ATU – Constant Volume: XG-FCI-600, XG-FCL-600, XG-FCQ-700		
	Fan Powered ATU – Variable Volume: XG-FVI-500, XG-FVL-600		
	Dual Duct ATU: XG-DD-500, XG-DH-500, XG-DS-600		
	Retrofit ATU: XG-SR-500, XG-RT-500, XG-RA-500		

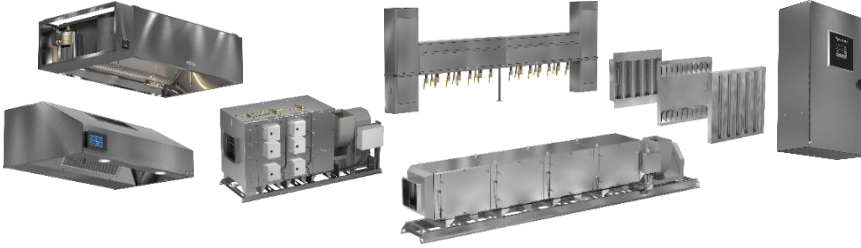
RTU	Rooftop Units		RTU@greenheck.com
	RT		1-866-205-0521

GRD	Grilles, Registers & Diffusers		GRD@greenheck.com
	Supply: XG-4000, XG-L Return: XG-RH, XG-CC5, XG-RP Filter: XG-RHF, XG-CC5F Spiral Duct: XG-4004P, XG-4004PCF Heavy Duty: XG-4500, XG-HDRH Transfer: XG-DG Industrial: XG-RL		(727) 431-6000
	Ceiling Diffusers		
	Square: XG-5700, XG-5750 Louvered: XG-5500, XG-9000 Perforated: XG-7500, XG-7600 Round: XG-3000, XG-3100 Concentric: XG-DAFCC5		
	Linear Diffusers & Grilles		
	Architectural: XG-AFL Linear Slot: XG-6600 Linear Bar: XG-2000 Louver Face: XG-LFL Plenums: XG-UP, XG-UPI		
	Plenum Slot Diffusers		
	Adjustable: XG-PHPS, XG-PHPS-IT Fixed: XG-PHC, XG-PHPS-E/J		
	Security Products		
	Lattice Face: XG-SGLF Perforated Face: XG-SGRP Suicide Deterrent: XG-SGRPSR		
	VAV Diffusers		
	Thermal: XG-MSCVH Electronic: XG-MSE Linear: XG-MLAD, XG-MVACH		
	Displacement Ventilation		
	Rectangular: XG-DD-CU, XG-DD-REC Round: XG-DD-90/180/360 In-Wall: XG-DD-Wall-1W		

Louver	Stationary Louvers			louvers@greenheck.com	
	ESD EDD EHM ESJ	ESK EDJ EDK	SE D		1-800-373-4866
	Operable Louvers				
	EAD EAH	ECD EACA EAC	EACC GCE		
	Wind Driven Rain Louvers				
	EHH	EVH			
	Hurricane Louvers				
	Note: (D or DE): Miami Dade Qualified X: Florida Product Approved				
Parts	EHV-550 EHV-550D EHV-901 EHV-901D EVH-501D	EVH-660D EHH-601D EHH-601DE ESD-635D ESD-635DE	EACA-601D EHH-501X ESD-435X ESD-635X		
	Specialty Louvers				
	ESU ESJ AFL AFJ	AFA EES BVE	BV F		
	Louvered Penthouses				
	WIH WRH	ESD-635PD EHH-601PD			

Parts	Parts			parts@greenheck.com	
					1-800-355-5354

PRV	Power Roof Ventilators / Roof Curbs		PRVfans@greenheck.com
	PRVs: CUBE, CUE, G, GB, USGF, AE/AS		1-800-984-8713 and Press 5
	Roof Curbs: GCC, GPI, GPS, GPR, GPF, GPFV, GPE/X, ATS/ ATR/ATE/ATI, Equipment Supports GESS/R, GESI/P, VCE, Adapters, Reducers, Pipe Portals		
	Gravity-Spun Aluminum: GRS/GRSF, RH		
TAP	ERV and MUA Service		tap@greenheck.com
	Energy Recovery Ventilators Make-up Air Indoor Air Handlers		1-800-240-0870 and Press 1
	Energy Recovery Ventilators - Pre-Sale		tap@greenheck.com
	Preconditioners: MINIV, MINIC, ECV, ERV, ERVe, ERM		1-800-240-0870 and Press 3
	Roof Curbs: GKD		
Make-up Air - Pre-Sale		tap@greenheck.com	
Direct Gas-Fired: DGX, TSU, VSU		1-800-240-0870 and Press 4	
Indirect Gas-Fired: IGX			
Non-Gas-Fired: MSX			

KVS

Support Contact Information
Pre-Sale Support

833-219-5128

kvs@greenheck.com
Post-Sale Tech Support/Service

1-800-371-6858 – Option #1

techsupport@accurex.com
Fire System Support

1-800-371-6858 – Option #5

coordination@accurex.com

KVS

Greenheck / Accurex Cross Reference

KVS	
GREENHECK	ACCUREX
GHEW	XBEW
GXEW	XXEW
GGEW	XGEW
GHDW	XBDW
GXDW	XXDW
GGDW	XGDW
GHEC	XBEC
GHEV	XBEV
GXEC	XXEC
GXEV	XXEV
GGEV	XGEV
GHFV	XBFV
GHEP	XBEP
GXEP	XXEP
GGEP	XGEP
M	XM
GO	XO
GD1	XD1
GD2	XD2
GD3	XD3
GRRS	XRRS

AXIAL/INLINE	
GREENHECK	ACCUREX
SQ	XID
BSQ	XIB
BDF	XIFB
KSQ	XKID
RSF	XRS
SAF	XRSW

CEILING EXHAUST	
GREENHECK	ACCUREX
SP	XCR
CSP	XIR

CF	
GREENHECK	ACCUREX
USF	XUEF

PRV	
GREENHECK	ACCUREX
AE	XRAE
AS	XRAS
CUBE	XCUBE
CUBE-HP	XCUBE-HP
CUBE-XP	XCUBE-XP
USGF	XRUBS
CUE	XCUE
GB	XREB
G	XRED

FETI	
GREENHECK	ACCUREX
TCB	XTIF
QEI	XQEI

TAP	
GREENHECK	ACCUREX
KSFB	XKSFB
KSFD	XKSFD
DG	XDG
DGX	XDGX
IGX	XIGX
MSX	XMSX
RV	XRV