

Cross Reference Guide

LSD Linear Slot Diffusers

Legacy Model	Description	Legacy Model XG-6600 Frame Style	New Model LSD Frame & Mounting Type
XG-6600	Linear Slot Diffusers for Supply and Return applications. Aluminum Construction. Built-in volume and directional pattern controllers. Available in 1 to 8 slots with ½", ¾", or 1" slot width. 1-1/2" Slot width is available in 1 to 4 slot units.	1-1/8" Border – No Hardware, Code -10 1-1/8" Border – Screw Mount, Code -11 1-1/8" Border – Concealed Mount, Code -12 3/4" Border – No Hardware, Code -20 3/4" Border – Concealed Mount, Code -22 1-13/16" Tape & Spackle Border – No Hardware, Code -50 1-13/16" Tape & Spackle Border – Concealed Mount, Code -52 25/32" Border – No Hardware, Code -40 25/32" Border – Concealed Mount, Code -42 1/2" Border – No Hardware, Code -30 1/2" Border – Concealed Mount, Code -32	AA – Standard AA – FSM AA – CM BB – Standard BB – CM CC – Standard CC – CM DD – Standard DD – CM FF – Standard FF – CM

LSD CAPS® Selection Guide

Model	Slot Width	Airflow Direction	Frame Type	Mounting	Border Type
LSD	50 - 1/2" 75 - 3/4" 10 - 1" 15 - 1-1/2"	Supply R - Return	-AA - 1-1/8" Border -BB - 3/4" Border -CC - 1-13/16" Tape & Spackle Border -DD - 25/32" Border -FF - 1/2" Border	Standard CM - Concealed FSM - Yes	-1 - Flush Surface Mount* -6 - T-Bar Lay-In -7 - Concealed Spline Module -8 - Tegular Module -9 - Bolt Slot / Donn Fineline Module -73 - Both Spline Frames -74 - Spline/Wall Frames -75 - Both Wall Frames

LSDMC Linear Slot Diffusers – Mitered Corner

Legacy Model	Description	Legacy Model XG-6600 Frame Style	New Model LSD Frame & Mounting Type
XG-6650MC XG-6675MC XG-6610MC XG-6615MC	Linear Slot Diffusers Mitered Corner are designed to maintain a continuous, aesthetically pleasing appearance in corners or angled areas, offering options for 45°, 90°, or 135° angles. Available in 1 to 8 slots with ½", ¾", or 1" slot width. 1-1/2" Slot width is available in 1 to 4 slot units.	1-1/8" Border – No Hardware, Code -10 1-1/8" Border – Screw Mount, Code -11 1-1/8" Border – Concealed Mount, Code -12 3/4" Border – No Hardware, Code -20 3/4" Border – Concealed Mount, Code -22 1-13/16" Tape & Spackle Border – No Hardware, Code -50 1-13/16" Tape & Spackle Border – Concealed Mount, Code -52 25/32" Border – No Hardware, Code -40 25/32" Border – Concealed Mount, Code -42 1/2" Border – No Hardware, Code -30 1/2" Border – Concealed Mount, Code -32	AA – Standard AA – FSM AA – CM BB – Standard BB – CM CC – Standard CC – CM DD – Standard DD – CM FF – Standard FF – CM

LSDMC CAPS® Selection Guide

Model	Slot Width	Frame Type	Mounting	Border Type	Degree Corner
LSDMC	50 - 1/2" 75 - 3/4" 10 - 1" 15 - 1-1/2"	-AA - 1-1/8" Border -BB - 3/4" Border -CC - 1-13/16" Tape & Spackle Border -DD - 25/32" Border -FF - 1/2" Border	Standard CM - Concealed FSM - Yes	-1 - Flush Surface Mount* -6 - T-Bar Lay-In -7 - Concealed Spline Module -8 - Tegular Module -9 - Bolt Slot / Donn Fineline Module -73 - Spline/Plaster Mounting Frame -74 - Wall-Mounted Spline/Plaster Mounting Frame -75 - Wall-Mounted Spline/Wall-Mounted Spline	45° 90° 135°

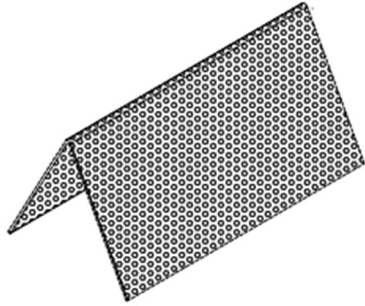
LSDTZ Linear Slot Diffusers – TechZone

Legacy Model	Description	Border Types
XG-6675TZ4 XG-6675TZ6 XG-6675RTZ4 XG-6675RTZ6	Linear Slot Diffusers compatible for use with Armstrong® TechZone™ and USG Logix™ Architectural Ceiling Systems. ¾" Slot width. Available in 4" wide and 6" wide unit widths. Available in 1 to 4 slots depending on frame type. Slot selection does not impact overall diffuser width. Supply units offer face adjustable pattern controllers to adjust volume or throw direction from vertical to horizontal. Return units feature the width, slot, and frame style options but omit the pattern controllers.	-6 – T-Bar Lay-In -9 – Bolt Slot / Donn Finline Module -NT – Narrow Tee

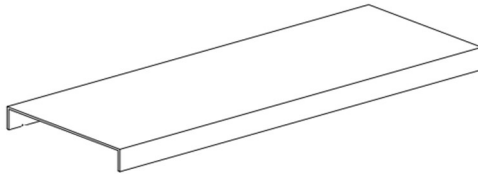
LSDTZ CAPS® Selection Guide

Model	Width	Airflow Direction	Border Type	Mounting
LSDTZ	4"	Supply	-6 – T-Bar Lay-In	Standard
	6"	Return	-9 – Bolt Slot / Donn Finline Module -NT – Narrow Tee	CM - Concealed

LSD-LS Linear Slot Diffusers – Light Shield

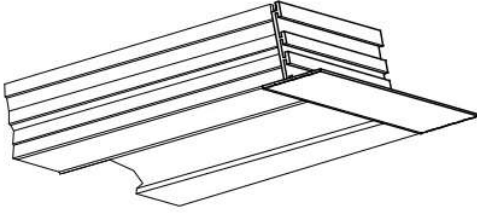
Legacy Model	New Model	Order Code Part String	Description	CAPS Selection
XG-6610-LS XG-6615-LS XG-6650-LS XG-6675-LS	LSD-LS	LSD-LS-10 LSD-LS-15 LSD-LS-50 LSD-LS-75	Aluminum insulated or non-insulated light shield to use with Linear Slot Diffusers. 	Select Model LSD-LS and the following: Slot Width – (10) 1", (15) 1.5", (50) 1/2", (75) 3/4" Length – 48" Only Slots – 1-8 Finish – 03 Black Insulation – Yes or No

LSD-BO Linear Slot Diffusers – Blank Off

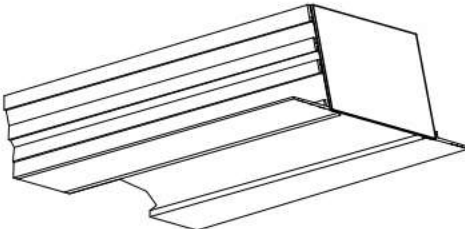
Legacy Model	New Model	Order Code Part String	Description	CAPS Selection
XG-6610-BO XG-6615-BO XG-6650-BO XG-6675-BO	LSD-BO	LSD-BO-10 LSD-BO-15 LSD-BO-50 LSD-BO-75	Aluminum Blank-Off section to use with Linear Slot Diffusers. 	Select Model LSD-BO and the following: Slot Width – (10) 1", (15) 1.5", (50) 1/2", (75) 3/4" Length – 48" Only Slots – 1-8 Finish – 03 Black

Cross Reference Guide

LSD-EB Linear Slot Diffusers – End Borders

Legacy Model	New Model	Order Code Part String	Description	CAPS Selection
XG-6610EB XG-6615EB XG-6650EB XG-6675EB	LSD-EB	LSD-EB-10 LSD-EB-15 LSD-EB-50 LSD-EB-75	End Border Only for Linear Slot Diffuser Model. 	Select Model LSD-EB and the following: Slot Width – (10) 1", (15) 1.5", (50) 1/2", (75) 3/4" Frame Type – AA, BB, DD, or FF Border Type – Select applicable Border Type. Slots – 1-8

LSD-EC Linear Slot Diffusers – End Caps

Legacy Model	New Model	Order Code Part String	Description	CAPS Selection
XG-6610EC XG-6615EC XG-6650EC XG-6675EC	LSD-EC	LSD-EC-10 LSD-EC-15 LSD-EC-50 LSD-EC-75	End Cap Only for Linear Slot Diffuser Model. 	Select Model LSD-EC and the following: Slot Width – (10) 1", (15) 1.5", (50) 1/2", (75) 3/4" Frame Type – AA, BB, CC, DD, or FF Border Type – Select applicable Border Type. Slots – 1-8

LSD-MTGHDW Linear Slot Diffusers – Mounting Hardware

Legacy Model	New Model	Order Code Part String	Description	CAPS Selection
XG-6610-MTGHDW XG-6615-MTGHDW XG-6650-MTGHDW XG-6675-MTGHDW	LSD-MTGHDW	LSD-MTGHDW-10 LSD-MTGHDW-15 LSD-MTGHDW-50 LSD-MTGHDW-75	Concealed Mounting Bracket with Screws for Linear Slot Diffusers. 24" or less2 Hanger Brackets 24" – 48"3 Hanger Brackets 48" – 60"4 Hanger Brackets 60" – 96"6 Hanger Brackets	Select Model LSD-MTGHDW and the following: Slot Width – (10) 1", (15) 1.5", (50) 1/2", (75) 3/4" Frame Type – AA, BB, CC, or FF Border Type – (-1) or (-6) Slots – 1-8